

## MY-COM A75/200

My-Com precision switches

Article number: 10221000

### Overview

- break function (NC) mechanical
- cable, 2 m
- -20 ... 75 °C
- IP 50



Picture similar



### Technical data

#### General data

Repeat accuracy	0.001 mm
Activating force	75 cN
Mech. pre-run / overrun	- / 1,5 mm approx.
Measurement type	Contact with medium
Direction of approach	Frontal

#### Electrical data

DC voltage max.	15 VDC
Switch. current DC max.	2 mA
AC voltage max.	24 VAC
Switch. current AC max.	50 mA

#### Electrical data

Output circuit	Break function (NC) mechanical
----------------	--------------------------------

#### Mechanical data


Activating pin	Zirconium oxide ZrO <sub>2</sub>
Housing material	Brass nickel plated
Dimension	8 mm
Type	Cylindrical threaded
Housing length	20 mm
Connection types	Cable, L=2 m

#### Ambient conditions

Operating temperature	-20 ... +75 °C
Protection class	IP 50

# MY-COM A75/200

## Dimension drawing

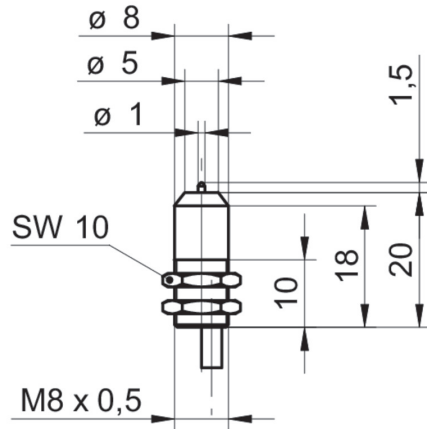

## Connection diagram

