


Inductive proximity switch

IFFK 08N3703/O1S35L

dimension drawing

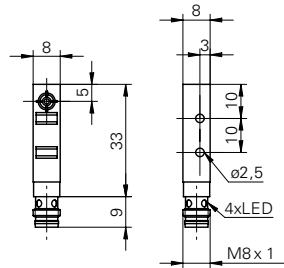

general data

mounting type	shielded
nominal sensing distance S_n	2 mm
hysteresis	3 ... 25 % of S_r
output indicator	4 port LED red

electrical data

switching frequency	< 5 kHz
voltage supply range +Vs	10 ... 30 VDC
current consumption max.	1,8E-005 mA
output circuit	NPN break function (NC)
voltage drop V_d	< 3 VDC
output current	< 200 mA
short circuit protection	yes
reverse polarity protection	yes

mechanical data

type	rectangular
material (sensing face)	PBT
housing material	PBT
dimension	8 mm
housing length	42 mm
connection types	connector M8


ambient conditions

operating temperature	-25 ... +75 °C
protection class	IP 67

photo



connection diagram

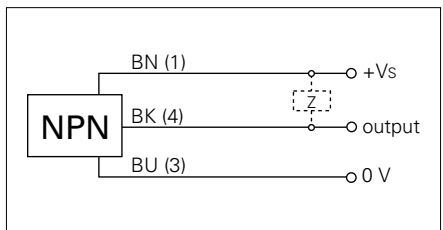

- PBT plastic housing