

ZVI-ARCUSM_24VDC_WEIß_120°

ARCUS-M white 24VDC with M8 connector

Article number: 11130183

overview

- flashable LED dark field illumination
- white
- radiation angle 120°
- 24 V
- M8/4-pin connector (cable has to be ordered separately)
- diameter: 120 mm



technical data

general data

manufacturer BÜCHNER Lichtsysteme GmbH

illumination data

color white

electrical data

number of poles 4
illumination connector • M8 connector
current 0,3 A
current at flash mode ≤ 0,6 A
voltage at flash mode ≤ 48 V DC
duty cycle 0-10%

electrical data

maximum flash duration 1 ms


mechanical data

construction design dark field illumination
dimensions Ø 120 mm
dimensions luminous area Ø external 74 mm Ø internal 68 mm
material of cover glass acrylic
weight ≤ 100 g
material aluminum (anodized, black)

environmental conditions

operating temperature max. 50 °C

dimension drawing

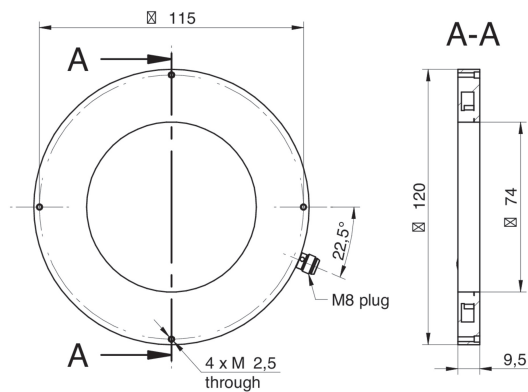


ZVI-ARCUSM_24VDC_WEIß_120°

ARCUS-M white 24VDC with M8 connector

Article number: 11130183

pin assignment

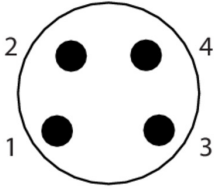

M8	signal
1:	LED +24V (pulsing 24-48 V)
2:	N.C.
3:	LED - (GND)
4:	N.C.