

ZVI-TOPLINED1_24VDC_SHWEIß_120°

TOP-LINE-D1 SH white 120° 24VDC M8 1-canal

Article number: 11130186

overview

- flashable LED bar light
- SH white
- radiation angle 120°
- 24 V
- M8/4-pin connector (cable has to be ordered separately)
- dimensions: 78 mm × 25 mm × 23 mm housing



technical data

general data

manufacturer: Bühner Lichtsysteme GmbH

illumination data

color: SH white

electrical data

number of poles: 4
illumination connector: • M8 connector
current: 0,3 A
current at flash mode: ≤ 0,42 A
voltage at flash mode: ≤ 48 V DC

electrical data

duty cycle: 0-10%
maximum flash duration: 1 ms


mechanical data

construction design: bar light
dimensions: 78 mm × 25 mm × 23 mm
material of cover glass: acrylic
weight: ≤ 80 g
material: aluminum (anodized)

environmental conditions

operating temperature: max. 50 °C

dimension drawing

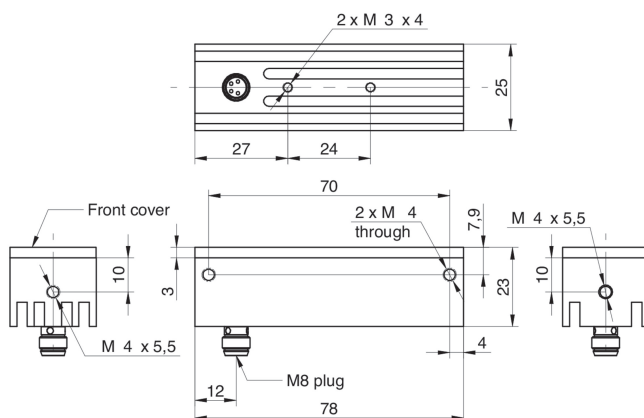


ZVI-TOPLINED1_24VDC_SHWEIß_120°

TOP-LINE-D1 SH white 120° 24VDC M8 1-canal

Article number: 11130186

pin assignment

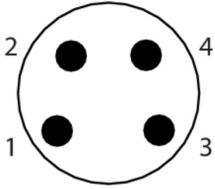

M8 signal

1: LED +24V (pulsing 24-48 V)

2: N.C.

3: LED - (GND)

4: N.C.