


overview

- Computar lens
- 16 mm
- F 2,4-16
- format 1"
- M.O.D. 0,1 m
- locating screw for aperture and focus
- C-mount

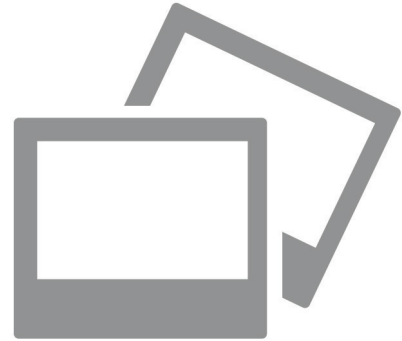

technical data

general data

manufacturer Computar

mechanical data

lens mount C-mount

dimensions 39,5 mm × 54,4 mm

max. outer diameter 39,5 mm (without knurled screws)
49,5 mm (with knurled screws)

max. length (excl. thread) 49,09 mm

weight ≤

filter thread M 35,5 × 0,5

lens data

lens resolution 20 MP

focal length 16 mm

lens data

focal range ≥ 12 mm ... < 25 mm

format 1"

aperture F2,4-16

aperture control manual

M.O.D. 0,1 m

horizontal angle of view 43,8 °

vertical angle of view 33,6 °

diagonal angle of view 53,2 °

at image format 12,8 × 9,6 mm

environmental conditions

operating temperature -10 ... +50 °C