


overview

- Kowa lens
- 6 mm
- F 1,4 - 16
- format 2/3"
- M.O.D. 0,1 m
- C-mount

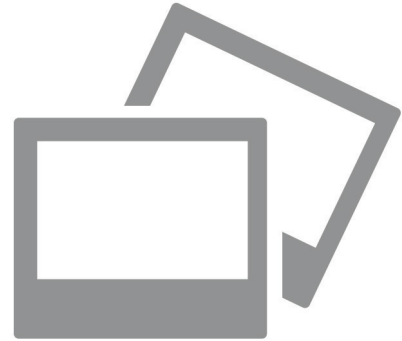

technical data

general data

manufacturer Kowa

mechanical data

lens mount C-mount

dimensions Ø 30 mm × 32,8 mm

max. outer diameter 30 mm (without knurled screws)
40 mm (with knurled screws)

max. length (excl. thread) 32,8 mm

weight ≤ 63 g

material metal

lens data

lens resolution 2,3 MP

focal length 6 mm

lens data

focal range < 12 mm

format 2/3"

aperture F1,4 - 16

aperture control manual

M.O.D. 0,1 m

horizontal angle of view 81,9 °

vertical angle of view 61,2 °

diagonal angle of view 102,9 °

at image format 6,6 × 8,8 mm

environmental conditions

operating temperature -10 ... +45 °C