


ZVL-LM8FC

Article number: 11700796

overview

- Kowa lens
- 8,5 mm
- F 2,5-16
- format 1,1"
- M.O.D. 0,1 m
- C-mount

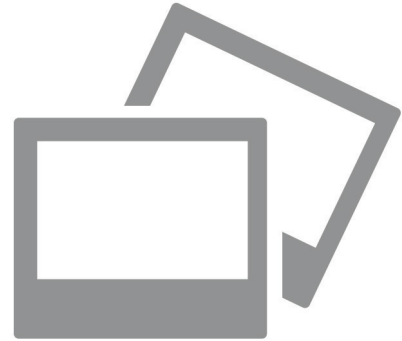

technical data

general data

manufacturer Kowa

mechanical data

lens mount C-mount

dimensions 64 mm × 79,7 mm

max. outer diameter 64 mm (without knurled screws)
64 mm (with knurled screws)

max. length (excl. thread) 73,3 mm

weight ≤ 230 g

filter thread M 62 × 0,75

lens data

lens resolution 12 MP

focal length 8,5 mm

lens data

focal range < 12 mm

format 1,1"

aperture F2,5-16

aperture control manual

M.O.D. 0,1 m

horizontal angle of view 79,2 °

vertical angle of view 63,8 °

diagonal angle of view 91,2 °

at image format 10,6 × 14,1 mm

environmental conditions

operating temperature -10 ... +50 °C