


## Cable GigE M12X/RJ45, 15,0 m

Article number: 11117632

### overview

- Gigabit Ethernet interface cable
- CAT6A
- M12/8-pin connector, X-coded (screw lock)
- not cable carrier compatible
- length 15,0 m

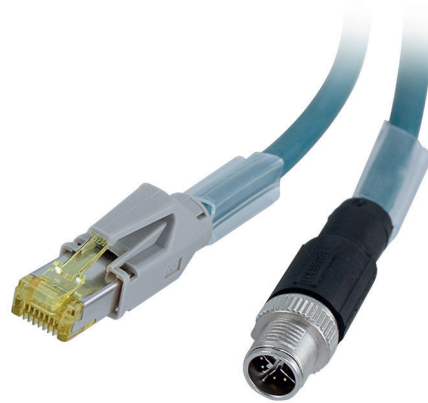

### technical data

#### electrical data

number of poles	8
connectors	M12/x-coded, screw lock RJ45

#### mechanical data

bending radius static	26 mm
bending radius moved in- stallation	52 mm
use in cable carriers	no
cable length [m]	15 m
weight	≤ 666 g
material	PUR



#### interface

data interface	GigE
----------------	------

#### environmental conditions

flame resistance	UL 758/1581 (horizontal) UL 758/1581 FT2
halogen-free	DIN VDE 0472 part 815 EN 50267-2-1
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-40 ... +70 °C @ T = measurement point
protection class	IP 65/67 (camera side)

## pin assignment

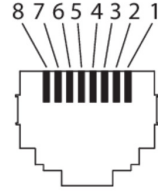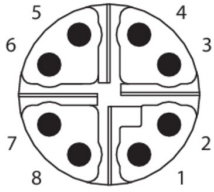

M12	RJ45	M12	RJ45
1:	1	7:	5
2:	2	8:	4
3:	3	5:	7
4:	6	6:	8