

ESG 34FH0200G

Shielded cable 8 wires, 2,0 m

Article number: 10127844

overview

- shielded process interface and power cable for Baumer *VisiLine*® IP cameras
- M12/8-pin female connector to open wires
- cable carrier compatible
- length 2,0 m



technical data

electrical data

shielding	yes
number of poles	8
connectors	M12 female connector, screw lock open wires

mechanical data

bending radius static	48 mm
bending radius moved in- stallation	59 mm
bending cycles	4000000
use in cable carriers	yes

mechanical data

cable length [m]	2 m
weight	≤ 114 g
material	PUR

interface

data interface	process interface
----------------	-------------------

environmental conditions


flame resistance	UL FT-2
operation temperature (static)	-25 ... +80 °C
protection class	IP 65/67 (camera side)

ESG 34FH0200G

Shielded cable 8 wires, 2,0 m

Article number: 10127844

pin assignment

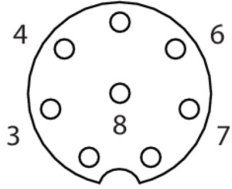

M12	color	M12	color
1:	WH	5:	GY
2:	BN	6:	PK
3:	GN	7:	BU
4:	YE	8:	RD