

ESW 33JP0200G

Connection cable M12/12-pin <i>VeriSens</i>®

Article number: 11048456

overview

- shielded connecting cable
- 90° angled M12/12-pin female connector to open wires
- cable carrier compatible
- length 2,0 m



technical data

electrical data

shielding	yes
number of poles	12
connectors	M12 female connector, angled, screw lock open wires

mechanical data

bending radius static	44 mm
bending radius moved in-stallation	88 mm
bending cycles	2000000
use in cable carriers	yes
cable length [m]	2 m

mechanical data

weight	≤ 210 g
material	PUR, PVC-free, halogen-free

interface

data interface	process interface
----------------	-------------------

environmental conditions


flame resistance	DIN EN 60332-1-2 and VW-1
halogen-free	DIN EN 50267-2-1
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-30 ... +80 °C
protection class	IP 65/67 (camera side)

ESW 33JP0200G

Connection cable M12/12-pin <i>VeriSens</i>®

Article number: 11048456

pin assignment

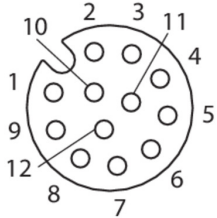

M12	color	M12	color
1:	BN	7:	BK
3:	WH	10:	VT
6:	YE	9:	RD
4:	GN	2:	BU
5:	PK	11:	GYPK
8:	GY	12:	RDBU