

Z-ESW 31FP0500

90° Cable 8 wires, 5,0 m, HX/SX

Article number: 11120461

overview

- process interface cable for Baumer HX/SX cameras
- 90° angled M8/8-pin female connector to open wires
- 90° rotated pin arrangement
- cable carrier compatible
- length 5,0 m



technical data

electrical data

shielding	no
number of poles	8
connectors	M8 female connector, angled, screw lock

mechanical data

bending radius static	25,5 mm
bending radius moved in-stallation	51 mm
bending cycles	4000000
use in cable carriers	yes
cable length [m]	5 m
weight	≤ 245 g
material	PUR

interface

data interface	process interface
----------------	-------------------

environmental conditions


flame resistance	DIN EN 60332-1-2 VDE 0482-332-1-2 IEC 60332-1-2 CSA FT-2
halogen-free	DIN EN 50267-2-1 IEC 60754-1 VDE 0482-267-2-1
resistance to oil	DIN EN 60811-2-1, 168 h at 100°C
operation temperature (static)	-50 ... +80 °C
protection class	IP 67 (camera side)

Z-ESW 31FP0500

90° Cable 8 wires, 5,0 m, HX/SX

Article number: 11120461

pin assignment

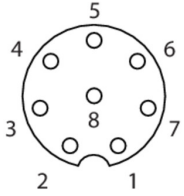

M8	wire color	M8	wire color
1:	WH	5:	GY
2:	BN	6:	PK
3:	GN	7:	BU
4:	YE	8:	RD