

Z-KSG 34A/KSG45AC1000G/E

Ethernet cable for cable carriers, 10,0 m

Article number: 11120361

overview

- shielded Ethernet cable
- straight M12/4-pin male connector to RJ45
- cable carrier compatible
- length 10,0 m



technical data

electrical data

number of poles	4
connectors	M12 male connector, screw lock RJ45

mechanical data

bending radius static	31 mm
bending radius moved in- stallation	62 mm
bending cycles	1000000
use in cable carriers	yes
cable length [m]	10 m

mechanical data

weight	≤ 600 g
material	PUR

interface

data interface	Ethernet
----------------	----------

environmental conditions


resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-50 ... +80 °C
protection class	IP 67 (camera side)

Z-KSG 34A/KSG45AC1000G/E

Ethernet cable for cable carriers, 10,0 m

Article number: 11120361

pin assignment

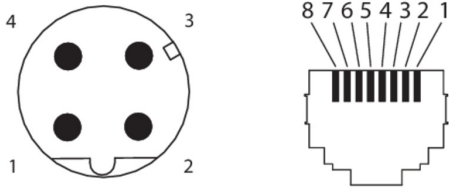

M12 RJ45

1:	1
3:	2
2:	3
4:	6