

Shielded cable 4 wires, 1,0 m

Article number: 11045713

overview

- shielded process interface cable (trigger and flash)
- M8/4-pin female connector to open wires
- cable carrier compatible
- length 1,0 m



technical data

electrical data

shielding	yes
number of poles	4
connectors	M8 female connector, screw lock open wires

mechanical data

bending radius static	25 mm
bending radius moved in- stallation	63 mm
bending cycles	250000
use in cable carriers	yes
cable length [m]	1 m
weight	≤ 40 g

mechanical data

material	PUR
----------	-----

interface

data interface	process interface
----------------	-------------------


environmental conditions

flame resistance	DIN EN 60332-2-2 VDE 0482-332-2-2 IEC 60332-2-2 UL/CSA FT-2
halogen-free	DIN EN 50267-2-1 IEC 60754-1 VDE 0482-267-2-1
protection class	IP 67 (camera side)

Shielded cable 4 wires, 1,0 m

Article number: 11045713

pin assignment

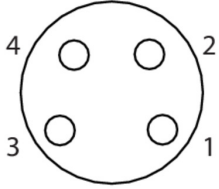

M8	color
1:	BN
2:	WH
4:	BK
3:	BU