

## ESG 32A/KSG32AH0030G

Article number: 11136134

### overview

- shielded extension cable
- straight M8/4-pin female connector to straight M8/4-pin male connector
- length: 0,3 m
- Phase-Out starting 08/20, alternative via sales



### technical data

#### electrical data

number of poles	4
connectors	M8 male connector, screw lock M8 female connector, screw lock

#### mechanical data

smallest bending radius static	22 mm
smallest bending radius moved installation	44 mm
bending cycles	4000000
use in cable carriers	yes
cable length [m]	0,3 m


#### mechanical data

weight	≤ 18 g
material	PUR, halogen-free

#### environmental conditions

flame resistance	DIN UL-Style 20549
halogen-free	DIN VDE 0472 part 815
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-40 ... +80 °C
operation temperature (moved installation)	-25 ... +80 °C

pin assignment

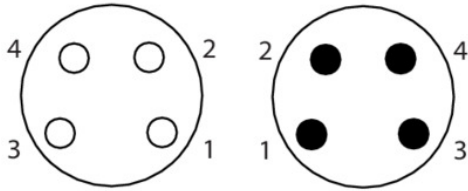

M8	M8
1:	1
4:	4
3:	3
2:	2