

ESG 32A/KSG32AH0150G

Extension cable for illumination

Article number: 11088882

overview

- shielded extension cable
- straight M8/4-pin female connector to straight M8/4-pin male connector
- length: 1,5 m
- Phase-Out starting 08/20, alternative via sales



technical data

electrical data

number of poles	4
connectors	M8 male connector, screw lock M8 female connector, screw lock

mechanical data

use in cable carriers	yes
cable length [m]	1,5 m
weight	≤ 75 g

mechanical data

material	PUR, halogen-free
----------	-------------------

environmental conditions


flame resistance	DIN UL-Style 20549
halogen-free	DIN VDE 0472 part 815
operation temperature (static)	-40 ... +80 °C
operation temperature (moved installation)	-25 ... +80 °C

ESG 32A/KSG32AH0150G

Extension cable for illumination

Article number: 11088882

pin assignment

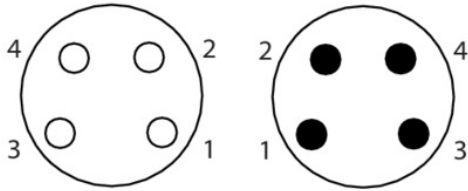

M8	M8
1:	1
4:	4
3:	3
2:	2