

 
## ESG 32AH0200G

Connection cable for external illumination

Article number: 10163693

### overview

- shielded adapter cable to connect illuminations to external power supply
- straight M8/4-pin female connector to open wires
- length: 2,0 m
- Phase-Out starting 08/20, alternative via sales



### technical data

#### electrical data

number of poles	4
connectors	M8 female connector, screw lock open wires

#### mechanical data

smallest bending radius static	24 mm
smallest bending radius moved installation	48 mm
bending cycles	10000000
use in cable carriers	yes
cable length [m]	2 m

#### mechanical data

weight	≤ 65 g
material	PUR, halogen-free

#### environmental conditions


flame resistance	DIN EN 60332-2-2 (20s)
halogen-free	DIN VDE 0472 part 815
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-40 ... +80 °C
operation temperature (moved installation)	-25 ... +80 °C
protection class	IP 65/67 (camera side)

## ESG 32AH0200G

Connection cable for external illumination

Article number: 10163693

### pin assignment

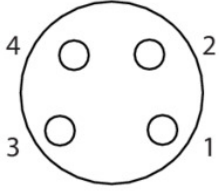

M8	color
----	-------

1:	BN
----	----

2:	WH
----	----

4:	BK
----	----

3:	BU
----	----