

ESG 34FH0500G

Shielded cable 8 wires, 5,0 m

Article number: 10129332

overview

- shielded process interface and power cable for Baumer *VisiLine*® IP cameras
- M12/8-pin female connector to open wires
- cable carrier compatible
- length 5,0 m
- Phase-Out starting 08/20, alternative via sales



technical data

electrical data

shielding	yes
number of poles	8
connectors	M12 female connector, screw lock open wires

mechanical data

smallest bending radius static	48 mm
smallest bending radius moved installation	59 mm
bending cycles	4000000
use in cable carriers	yes

mechanical data

cable length [m]	5 m
weight	≤ 284 g
material	PUR

interface

data interface	process interface
----------------	-------------------

environmental conditions


flame resistance	UL FT-2
operation temperature (static)	-25 ... +80 °C
protection class	IP 65/67 (camera side)

ESG 34FH0500G

Shielded cable 8 wires, 5,0 m

Article number: 10129332

pin assignment

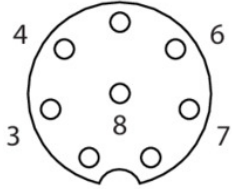

M12	color	M12	color
1:	WH	5:	GY
2:	BN	6:	PK
3:	GN	7:	BU
4:	YE	8:	RD