


KSG 34A/KSG45AP0200G

Ethernet cable, 2,0 m

Article number: 11048502

overview

- shielded Ethernet cable
- straight M12/4-pin male connector to RJ45
- length 2,0 m
- Phase-Out starting 08/20, alternative via sales

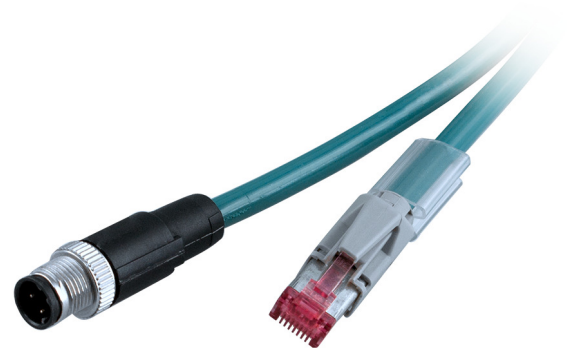

technical data

electrical data

number of poles	4
connectors	M12 male connector, screw lock

mechanical data

smallest bending radius static	26 mm
smallest bending radius moved installation	52 mm
use in cable carriers	no
cable length [m]	2 m
weight	≤ 115 g

mechanical data

material	PUR
----------	-----

interface

data interface	Ethernet
----------------	----------

environmental conditions


flame resistance	DIN EN 60332-1-2
halogen-free	IEC 60754-1
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-20 ... +80 °C
protection class	IP 65/67 (camera side)

KSG 34A/KSG45AP0200G

Ethernet cable, 2,0 m

Article number: 11048502

pin assignment

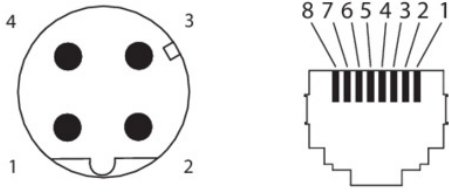

M12	RJ45
1:	1
3:	2
2:	3
4:	6