


KSW 33A/KSG45AP0200G/E

90° angled Ethernet cable, 2,0 m

Article number: 11048592

overview

- shielded Ethernet cable
- 90° angled M12/4-pin male connector to RJ45
- length 2,0 m
- Phase-Out starting 08/20, alternative via sales

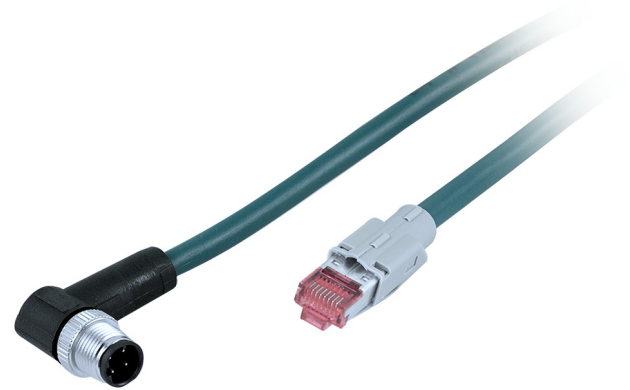

technical data

electrical data

number of poles 4

mechanical data

smallest bending radius static 26 mm

smallest bending radius moved installation 52 mm

use in cable carriers no

cable length [m] 2 m

weight ≤ 118 g

material PUR

interface

data interface Ethernet

environmental conditions

flame resistance DIN EN 60332-1-2

halogen-free IEC 60754-1

resistance to oil DIN EN 60811-2-1

operation temperature (static) -20 ... +80 °C


protection class IP 65/67 (camera side)

KSW 33A/KSG45AP0200G/E

90° angled Ethernet cable, 2,0 m

Article number: 11048592

pin assignment

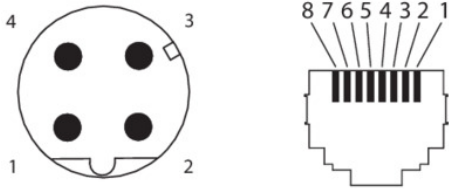

M12 RJ45

1:	1
3:	2
2:	3
4:	6