

Z-ESG 32FP1000G

Shielded cable 8 wires, female connector, 10,0 m

Article number: 11138385

overview

- shielded process interface cable
- M8/8-pin female connector to open wires
- cable carrier compatible
- length 10,0 m
- Phase-Out starting 08/20, alternative via sales



technical data

electrical data

shielding	yes
number of poles	8
connectors	M8 female connector, screw lock open wires

mechanical data

smallest bending radius static	29,5 mm
smallest bending radius moved installation	59 mm
bending cycles	2000000
use in cable carriers	yes
cable length [m]	10 m

mechanical data

weight	≤ 490 g
material	PUR

interface

data interface	process interface
----------------	-------------------

environmental conditions


flame resistance	UL 758/1581 (horizontal) UL 758/1581 FT2
halogen-free	DIN VDE 0472 part 815 EN 50267-2-1
resistance to oil	DIN EN 60811-2-1, 168 h at 100°C
operation temperature (static)	-25 ... +80 °C
protection class	IP 67 (camera side)

Z-ESG 32FP1000G

Shielded cable 8 wires, female connector, 10,0 m

Article number: 11138385

pin assignment

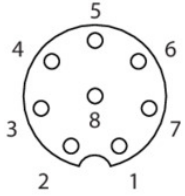

M8	wire color	M8	wire color
1:	WH	5:	GY
2:	BN	6:	PK
3:	GN	7:	BU
4:	YE	8:	RD