

Connection cable with connector M23 / rear mount socket M23 (S2BG12/H2SG12), 5 m

Article number: 11066188

Overview

- Shielded connection cable with M23-female connector (12-pin) and rear mount socket M23 (male, 12-pin)



Technical data

Cable specifications

Material	Cable sheath: PUR black
Weight approx.	550 g
Cable length	5 m
Operating temperature	-40...+100 °C (fixed cable) -25...+100 °C (moved cable)



Cable specifications

Outer diameter	≈ 7.5 mm
Connection	Connector M23, 12-pin Rear mount socket M23 (male, 12-pin)

Terminal assignment

Connector S2BG12 Rear mount socket H2SG12

Pin 5	Pin 5
Pin 6	Pin 6
Pin 8	Pin 8
Pin 1	Pin 1
Pin 3	Pin 3
Pin 4	Pin 4
Pin 12	Pin 12
Pin 10	Pin 10
Pin 2	Pin 2
Pin 11	Pin 11
Pin 7 (NC)	Pin 7 (NC)
Pin 9 (NC)	Pin 9 (NC)
Housing/Shield	Housing/Shield

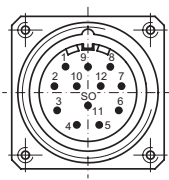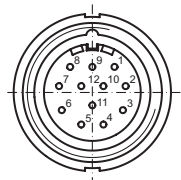

Dimensions

connector type 2,
bush contacts, straight,
12-pin, EMV
S2BG12

rear mount socket type 2,
pin contacts, straight,
12-pin, EMV
H2SG12

