


# Connection cable connector M12 / connector D-SUB, 1 m - Option 3232

Article number: 11135370

## Overview

- Connecting cable shielded with connector M12, 8-pin, female contacts on connector D-SUB, 9-pin, male contacts
- For encoder with connection option 3232 only

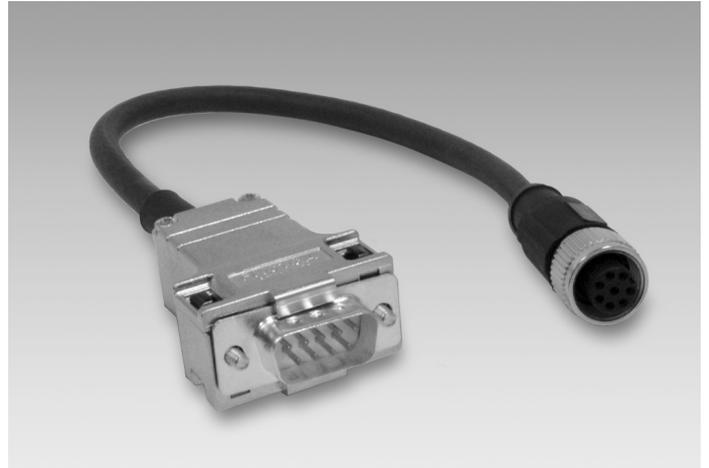

## Technical data

### Cable specifications


Material	Cable sheath: PUR black, halogen free
Weight approx.	180 g

### Cable specifications

Cable length	1 m
Operating temperature	-10...+60 °C
Outer diameter	≈ 5.9 mm

## Terminal assignment

Connector M12	Connector D-SUB
Pin 1	Pin 6
Pin 2	Pin 1
Pin 3	Pin 7
Pin 4	Pin 2
Pin 5	Pin 8
Pin 6	Pin 3
Pin 7	Pin 5
Pin 8	Pin 4
NC	Pin 9
Housing/Shield	Housing/Shield

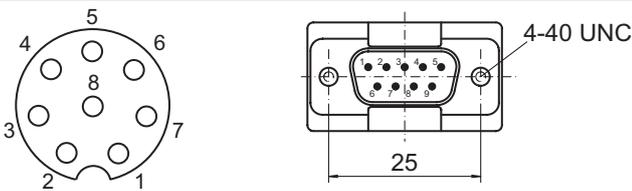

## Dimensions

