

# Connection cable connector M23 (CW) / D-SUB (S2BG12/K4BG9), 20 m

Article number: 11068198

## Overview

- Shielded connection cable with connector M23 (12-pin, female, clockwise (CW)) and D-SUB-female connector (9-pin)



## Technical data

### Cable specifications


|                |                         |
|----------------|-------------------------|
| Material       | Cable sheath: PUR black |
| Weight approx. | 2050 g                  |
| Cable length   | 20 m                    |

### Cable specifications

|                       |                                                            |
|-----------------------|------------------------------------------------------------|
| Operating temperature | -40...+100 °C (fixed cable)<br>-25...+100 °C (moved cable) |
| Outer diameter        | ≈ 7.5 mm                                                   |

## Terminal assignment

|                  |                 |
|------------------|-----------------|
| Connector S2BG12 | Coupling K4BG 9 |
| Pin 5            | Pin 3           |
| Pin 6            | Pin 2           |
| Pin 8            | Pin 1           |
| Pin 1            | Pin 9           |
| Pin 3            | Pin 7           |
| Pin 4            | Pin 6           |
| Pin 12           | Pin 4           |
| Pin 10           | Pin 5           |
| Pin 2 (NC)       | Pin 8 (NC)      |
| Pin 11           | NC              |
| Pin 7            | NC              |
| Pin 9            | NC              |
| Housing/Shield   | Housing/Shield  |

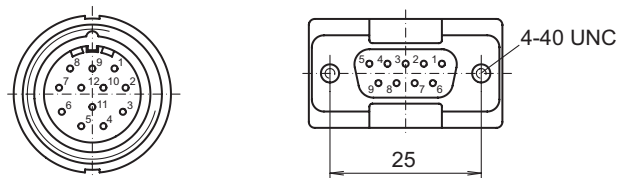

## Dimensions

connector type 2,  
bush contacts,  
straight, 12-pin, EMV  
S2BG12

coupling type 4,  
bush contacts,  
straight, 9-pin, EMV  
K4BG 9

