

Female connector M23, 12-pin, CCW, with cable 2

m

Article number: 11222561

Overview

- Connection cable shielded with female connector M23, open cable end
- Cable [4x2x0.14 mm²], cable length 2 m
- Cable coating PVC
- Colour code according to DIN 47100
- UL/CSA approval
- Connector M23: 12-pin, female, counterclockwise (CCW). Suitable for cable connection to flange connector M23 (12-pin, male, clockwise (CW)).
- Temperature range -40...+85 °C (fixed installation)



Technical data

Cable specifications


Shield	Common low capacity shield
Cable length	2 m
Cable type	4x2x0.14 mm ²
Bending radius	6 x cable diameter (fixed) 15 x cable diameter (in motion)
Outer diameter	≈ 6.4 mm

Cable specifications

Operating temperature	-40...+85 °C (fixed cable)
Connection	Connector M23, 12-pin
Weight approx.	195 g
Material	Cable sheath: PVC grey
Approval	UL/CSA approval


Terminal assignment

Connector M23	Core colour
Pin 1	pink
Pin 2	—
Pin 3	blue
Pin 4	red
Pin 5	green
Pin 6	yellow
Pin 7	—
Pin 8	grey
Pin 9	—
Pin 10	white
Pin 11	—
Pin 12	brown
Housing	Shield

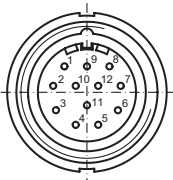

Connector M23, female, 12-pin, counterclockwise (CCW)

Dimensions

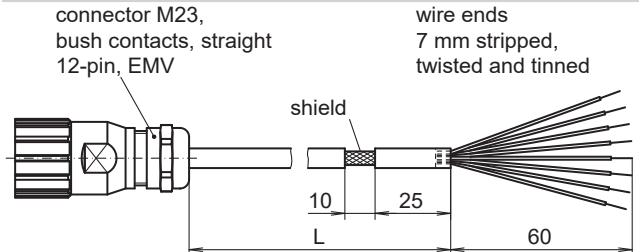

Suitable for

EIL580-B - M23 CW, EIL580-SC - M23 CW, EIL580-SY - M23 CW, EIL580-T - M23 CW