


Overview

- Side A: Wires with Crimp contacts; Side B: Wires with Crimp contacts and shielding with Crimp contacts
- Cable structure: 5 x 0,34 mm²
- TPE; suitable for Food & Beverage
- Good resistance against chemicals and UV
- Halogen free

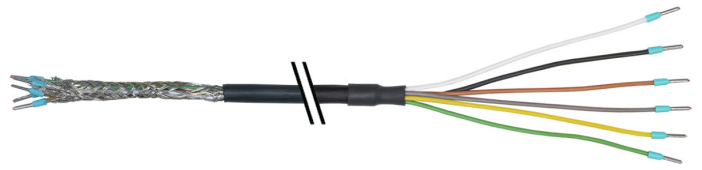

Technical data

Side A

| | |
|-------------------------------|-------------------------------------------------------|
| Side A: Shielding length | 72 mm |
| Side A: Shielding processing | Not processed |
| Side A: Crimp terminal wire 1 | 0.34 mm ² ; contact length: 6 mm; isolated |
| Side A: Crimp terminal wire 2 | 0.34 mm ² ; contact length: 6 mm; isolated |
| Side A: Crimp terminal wire 3 | 0.34 mm ² ; contact length: 6 mm; isolated |
| Side A: Crimp terminal wire 4 | 0.34 mm ² ; contact length: 6 mm; isolated |
| Side A: Crimp terminal wire 5 | 0.34 mm ² ; contact length: 6 mm; isolated |

Side B

| | |
|----------------------------------|-------------------------------------------------------|
| Side B: Shielding length | 100 mm |
| Side B: Shielding processing | Twisted and reduced to 0.34 mm ² |
| Side B: Shielding crimp terminal | 0.34 mm ² ; contact length: 6 mm; isolated |
| Side B: Crimp terminal wire 1 | 0.34 mm ² ; contact length: 6 mm; isolated |
| Side B: Crimp terminal wire 2 | 0.34 mm ² ; contact length: 6 mm; isolated |

Side B

| | |
|-------------------------------|-------------------------------------------------------|
| Side B: Crimp terminal wire 3 | 0.34 mm ² ; contact length: 6 mm; isolated |
| Side B: Crimp terminal wire 4 | 0.34 mm ² ; contact length: 6 mm; isolated |
| Side B: Crimp terminal wire 5 | 0.34 mm ² ; contact length: 6 mm; isolated |

Cables

| | |
|---------------------------|----------------------|
| Cable length | 200 cm |
| Length tolerance | + 10 cm |
| No. of wires | 5 |
| Shielded | Yes |
| External sheath: Material | TPE |
| External sheath: Color | Black |
| Cable diameter | 6.2 mm |
| Wire cross section | 0.34 mm ² |

Mechanical data

| | |
|-------------------------|--------------------------|
| Bending radius (mobile) | min. 10 × outer diameter |
| Bending radius (fixed) | min. 4 × outer diameter |

Environmental conditions

| | |
|----------------------------------|----------------------------------------|
| Cable: Temperature range (fixed) | - 50 ...+ 90 °C |
| Cable: Chemical resistance | ECOLAB material resistance test passed |

Dimension drawing

