

Overview

- Male straight
- M12 , 5-pole, A-coded
- max. 0,75mm², 4 - 6mm, shielded




Technical data


Side A		Side A	
Head A: Connection	M12	Wire cross section (max.)	0.75 mm ²
Head A: Angle cable outlet	0°	Cable diameter (max.)	6 mm
Head A: Gender	Male	Cable diameter (min.)	4 mm
Head A: Coding	A	Electrical data	
Head A: Shielded	Yes	Operating voltage	max. 50 V AC/DC 0
Head A: No. of poles	5	Operating current per contact	max. 4 A
Head A: Tightening torque	0.6 Nm	Mechanical data	
Head A: Knurled nut material	GD-Zn,Ni	Head A: Degree of protection	IP67
Head A: Body color	Black	Environmental conditions	
Head A: Gasket material	Elastomer	Head A: Pollution degree	3
Max. AWG	18	Commercial data	
Connection method	Screw terminals	Eclass	27440102

Side A

Technical drawing

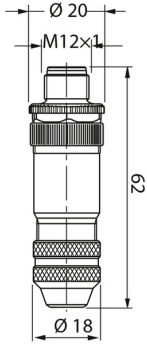

Coding

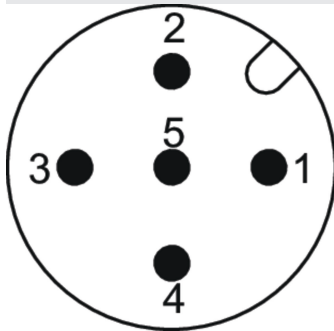

Connection diagram

