

CNAC 25E 7-pin Mil Spec Mating Connector + cable

L=30 ft (9.15 m)

Article number: 11078446

Overview

- Shielded connection cable with mating connector NAC 25E 7-pin Mil Spec (female contacts) and stranded wires 0.14 mm² with wire end sleeves
- Cable length 30 ft (9.15 m)



Technical data

Cable specifications

Weight approx.	640 g
Cable length	30 ft (9.15 m)


Cable specifications

Operating temperature	-40...+100 °C (fixed cable) -30...+100 °C (moved cable)
Outer diameter	≈ 7,0 mm


Terminal assignment

Connector with cable sw10, 7-pin

Connector	Core colour	Assignment
Pin A	green	Track A
Pin B	grey	Track B
Pin C	pink	Track Z
Pin D	red	+Vs
Pin E	—	—
Pin F	blue	0 V
Pin G	yellow	Housing

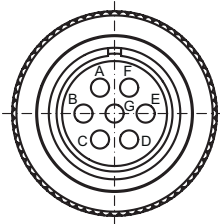

Dimensions

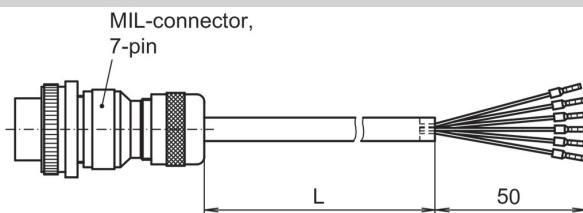

Suitable for

HS35F, HS35P - Programmable