

CNAC 25E0500 7-pin Mil Spec Mating Connector + cable L=5 m (Stock in US)

Article number: 11150863

Overview

- Shielded connection cable with mating connector NAC 25E 7-pin Mil Spec (female contacts) and stranded wires 0.14 mm² with wire end sleeves
- Cable length 5 m
- Stock in US



Technical data

Cable specifications

Cable length	5 m
Operating temperature	-40...+100 °C (fixed cable) -30...+100 °C (moved cable)


Cable specifications

Outer diameter	≈ 7,0 mm
----------------	----------


Terminal assignment

Connector with cable sw10, 7-pin

Connector	Core colour	Assignment
Pin A	green	Track A
Pin B	grey	Track B
Pin C	pink	Track Z
Pin D	red	+Vs
Pin E	—	—
Pin F	blue	0 V
Pin G	yellow	Housing

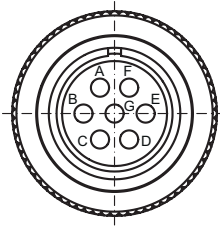

Dimensions

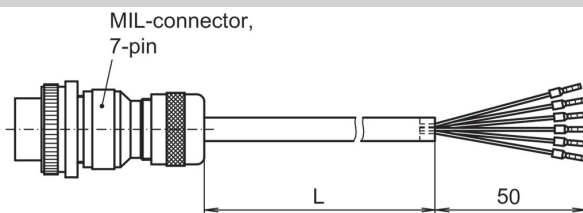

Suitable for

HS35F, HS35P - Programmable