

CNAC 29H 10-pin Mil Spec Mating Connector + cable L=10 ft (3.05 m)

Article number: 11078307

Overview

- Shielded connection cable with mating connector NAC 29H 10-pin Mil Spec (female contacts) and stranded wires 0.14 mm² with wire end sleeves
- Cable length 10 ft (3.05 m)



Technical data

Cable specifications

Weight approx.	275 g
Cable length	10 ft (3.05 m)


Cable specifications

Operating temperature	-40...+100 °C (fixed cable) -30...+100 °C (moved cable)
Outer diameter	≈ 7,0 mm

Terminal assignment

Connector with cable sw10, 10-pin

Connector	Core colour	Assignment
Pin A	green	Track A (Track A +)
Pin B	grey	Track B (Track B +)
Pin C	pink	Track Z (Track Z +)
Pin D	red	+Vs
Pin E	violet	$\overline{\text{Err}}$
Pin F	blue	0 V
Pin G	yellow	Housing
Pin H	brown	Track A inv. (Track A -)
Pin I	black	Track B inv. (Track B -)
Pin J	white	Track Z inv. (Track Z -)

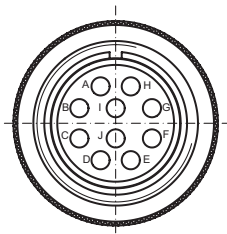

Suitable for

HS35F, HS35P - Programmable, HS35S - Sine

Dimensions

