

# CNAC 29H0200 10-pin Mil Spec Mating Connector

+ cable L=2 m (Stock in US)

Article number: 11151376

## Overview

- Shielded connection cable with mating connector NAC 29H 10-pin Mil Spec (female contacts) and stranded wires 0.14 mm<sup>2</sup> with wire end sleeves
- Cable length 2 m
- Stock in US



## Technical data

### Cable specifications

Cable length	2 m
Operating temperature	-40...+100 °C (fixed cable) -30...+100 °C (moved cable)


### Cable specifications

Outer diameter	≈ 7,0 mm
----------------	----------

## Terminal assignment

### Connector with cable sw10, 10-pin

Connector	Core colour	Assignment
Pin A	green	Track A (Track A +)
Pin B	grey	Track B (Track B +)
Pin C	pink	Track Z (Track Z +)
Pin D	red	+Vs
Pin E	violet	$\overline{\text{Err}}$
Pin F	blue	0 V
Pin G	yellow	Housing
Pin H	brown	Track A inv. (Track A -)
Pin I	black	Track B inv. (Track B -)
Pin J	white	Track Z inv. (Track Z -)

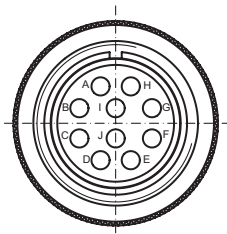

## Suitable for

HS35F, HS35P - Programmable, HS35S - Sine

## Dimensions

