

# Cable GigE M12/RJ45, 5,0 m, chain

Article number: 11003440

## Overview

- Gigabit Ethernet interface cable
- for TXG-I7 cameras
- CAT6
- M12 (screw lock) to RJ45
- cable carrier compatible
- length 5,0 m



## Technical data

### Electrical data

Number of poles	8
Connectors	M12 male connector, screw lock

### Mechanical data

Smallest bending radius static	45 mm
Bending cycles	1000000
Use in cable carriers	yes
Cable length [m]	5 m

### Mechanical data

Weight	≤ 363 g
Material	PVC

### Interface

Data interface	GigE
----------------	------


### Environmental conditions

Flame resistance	UL20276 (80°C, 30V)
Protection class	IP 68 (camera side)

# Cable GigE M12/RJ45, 5,0 m, chain

Article number: 11003440

## Pin assignment

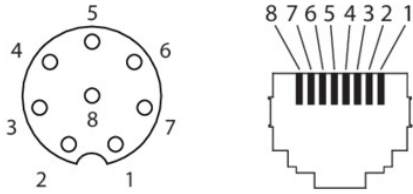

M12	RJ45	M12	RJ45
6:	1	1:	5
4:	2	8:	6
5:	3	2:	7
7:	4	3:	8