

## Cable GigE M12X/RJ45, STP 15.0m, flex

Article number: 11195762

### overview

- Gigabit Ethernet interface cable
- CAT6A
- M12/8-pin connector, X-coded (screw lock) to RJ45
- cable carrier compatible
- length 15,0 m



### technical data

#### electrical data

|                 |                                 |
|-----------------|---------------------------------|
| number of poles | 8                               |
| connectors      | M12/x-coded, screw lock<br>RJ45 |

#### mechanical data

|                                   |                     |
|-----------------------------------|---------------------|
| smallest bending radius<br>static | 35,4 mm             |
| bending cycles                    | 1000000             |
| use in cable carriers             | yes, flexible cable |
| cable length [m]                  | 15 m                |

#### mechanical data

|          |                   |
|----------|-------------------|
| weight   | ≤ 1050 g          |
| material | TPU, halogen-free |



#### interface

|                |                 |
|----------------|-----------------|
| data interface | 10 GigE<br>GigE |
|----------------|-----------------|

#### environmental conditions

|                  |                     |
|------------------|---------------------|
| flame resistance | UL AWM 20622        |
| protection class | IP 67 (camera side) |

## pin assignment

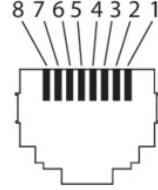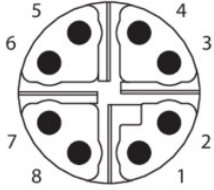

| M12 | RJ45 | M12 | RJ45 |
|-----|------|-----|------|
| 1:  | 1    | 7:  | 5    |
| 2:  | 2    | 8:  | 4    |
| 3:  | 3    | 5:  | 7    |
| 4:  | 6    | 6:  | 8    |