

## Cable GigE M12X/RJ45, STP 2.0m, flex

Article number: 11185139

### overview

- Gigabit Ethernet interface cable
- CAT6A
- M12/8-pin connector, X-coded (screw lock) to RJ45
- cable carrier compatible
- length 2,0 m



### technical data

#### electrical data

number of poles	8
connectors	M12/x-coded, screw lock RJ45

#### mechanical data

smallest bending radius static	35,4 mm
bending cycles	1000000
use in cable carriers	yes, flexible cable
cable length [m]	2 m

#### mechanical data

weight	≤ 140 g
material	TPU, halogen-free



#### interface

data interface	10 GigE GigE
----------------	-----------------

#### environmental conditions

flame resistance	UL AWM 20622
protection class	IP 67 (camera side)

## pin assignment

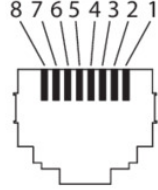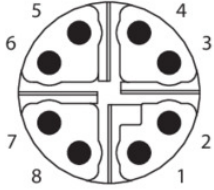

M12	RJ45	M12	RJ45
1:	1	7:	5
2:	2	8:	4
3:	3	5:	7
4:	6	6:	8