

## overview

- Gigabit Ethernet interface cable
- CAT5e
- RJ45 (screw lock) to RJ45
- suitable for cable carrier and torsion applications
- length 30,0 m



## technical data

### electrical data

number of poles	8
connectors	RJ45, screw lock RJ45

### mechanical data

bending radius static	42 mm
bending cycles	10000000
use in cable carriers	yes

### mechanical data

cable length [m]	30 m
weight	≤ 2400 g
material	PVC, lead-free


### interface

data interface	GigE
----------------	------

### environmental conditions

flame resistance	UL20276 80°C / 30V
------------------	--------------------

pin assignment

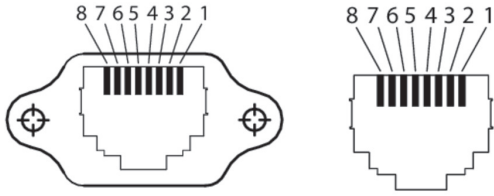

RJ45S RJ45		RJ45S RJ45	
1:	1	5:	5
2:	2	6:	6
3:	3	7:	7
4:	4	8:	8