

# Connection cable 2 m shielded with female connector M12, 8-pin, straight (ESG 34FH0200G)

Article number: 10127844

## Overview

- Connection cable shielded with female connector M12, shielding on cap nut
- Cable length 2 m
- 8-pin version
- Cable coating PUR
- Halogen-free
- Suitable for flexible cable carriers
- UL listed, number E315836



## Technical data

### Cable specifications


Weight approx.	124 g
Cable length	2 m
Operating temperature	-40...+80 °C (fixed cable) -25...+80 °C (moved cable)

### Cable specifications


Outer diameter	≈ 5,9 mm
Connection	Connector M12, 8-pin

## Terminal assignment

Female connector M12	Core colour
Pin 1	white
Pin 2	brown
Pin 3	green
Pin 4	yellow
Pin 5	grey
Pin 6	pink
Pin 7	blue
Pin 8	red
Connector Housing	Shield/Housing

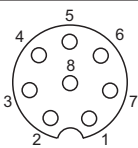

## Dimensions

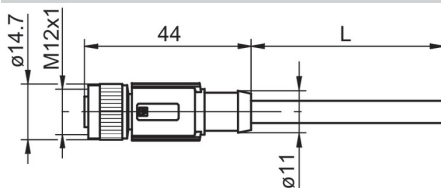

## Suitable for

EIL580-B, EIL580-B - Option 6301, EIL580-SC, EIL580-SQ, EIL580-SY, EIL580-T, EIL580-T - Option 6301, EIL580P-B, EIL580P-SC, EIL580P-SQ, EIL580P-SY, EIL580P-T, GI357, GIM500R