

# Connection cable connector M23 (CW) / D-SUB (S2BG12/K4BG9), 10 m

Article number: 11068195

## Overview

- Shielded connection cable with connector M23 (12-pin, female, clockwise (CW)) and D-SUB-female connector (9-pin)



## Technical data

### Cable specifications


Material	Cable sheath: PUR black
Weight approx.	1050 g
Cable length	10 m

### Cable specifications

Operating temperature	-40...+100 °C (fixed cable)
	-25...+100 °C (moved cable)
Outer diameter	≈ 7.5 mm

## Terminal assignment

Connector S2BG12	Coupling K4BG 9
Pin 5	Pin 3
Pin 6	Pin 2
Pin 8	Pin 1
Pin 1	Pin 9
Pin 3	Pin 7
Pin 4	Pin 6
Pin 12	Pin 4
Pin 10	Pin 5
Pin 2 (NC)	Pin 8 (NC)
Pin 11	NC
Pin 7	NC
Pin 9	NC
Housing/Shield	Housing/Shield

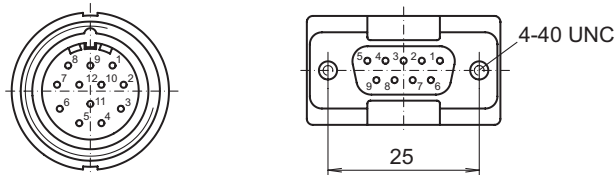

## Dimensions

connector type 2,  
bush contacts,  
straight, 12-pin, EMV  
S2BG12

coupling type 4,  
bush contacts,  
straight, 9-pin, EMV  
K4BG 9

