

Connection cable with FCI, 8-pin / wire end sleeves,

1 m

Article number: 11071188

Overview

- Shielded connection cable with FCI-female coupling (8-pin) and stranded wires 0.14 mm² with wire end sleeves
- Qualified for operating temperature up to +120 °C
- Assembly by customer possible



Technical data

Cable specifications

 
Material	Cable sheath: SABIX® grey, halogen free
Weight approx.	100 g
Cable length	1 m

Cable specifications

Operating temperature	-30...+120 °C
Outer diameter	≈ 6,8 mm
Connection	Wire end sleeves Coupling FCI, 8-pin, female

Terminal assignment


Connector	Core colour
Pin 1	red
Pin 2	blue
Pin 3	green
Pin 4	brown
Pin 5	grey
Pin 6	black
Pin 7	pink
Pin 8	white
shield = sleeve	transparent



Dimensions

coupling type 21,
bush contacts,
8-pin
K21BG8

stranded wires 0.14 mm²
with wire end sleeves

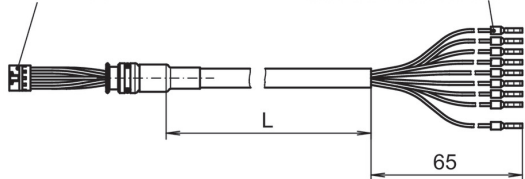

Suitable for

ITD21H00 HT, ITD21H01 HT