

# Connection cable with coupling M12, 4-pin, 0.7 m

Article number: 11104310

## Overview

- Screened connection cable with coupling M12, 4-pin
- UL/CSA - approval
- Temperature range -20...+85 °C (-30...+85 °C with fixed installation)
- Assembly by customer possible



## Technical data

### Cable specifications


Weight approx.	45 g
Cable length	0.7 m

### Cable specifications


Operating temperature	-30...+85 °C (fixed cable) -20...+85 °C (moved cable)
Outer diameter	≈ 5 mm

## Terminal assignment

Coupling K21BG8	Coupling K10SG4
Pin 1	Pin 1
Pin 2	Pin 3
Pin 3	Pin 4
Pin 4	NC
Pin 5	Pin 2
Pin 6	NC
Pin 7	NC
Pin 8	NC
shield/housing	shield/housing

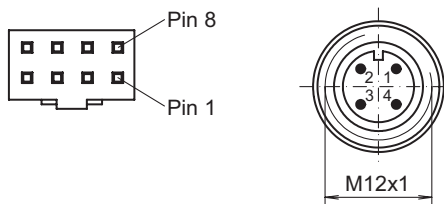

## Dimensions

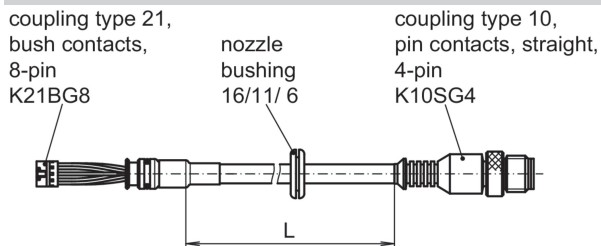

## Suitable for

ITD21H00