


# Connection cable with crimp contacts (UL/CSA),

## 0.2 m

Article number: 11079112

### Overview

- Shielded connection cable with stranded wires 0.14 mm<sup>2</sup> and crimp contacts 61.171.80
- UL/CSA certification
- Assembly by customer possible

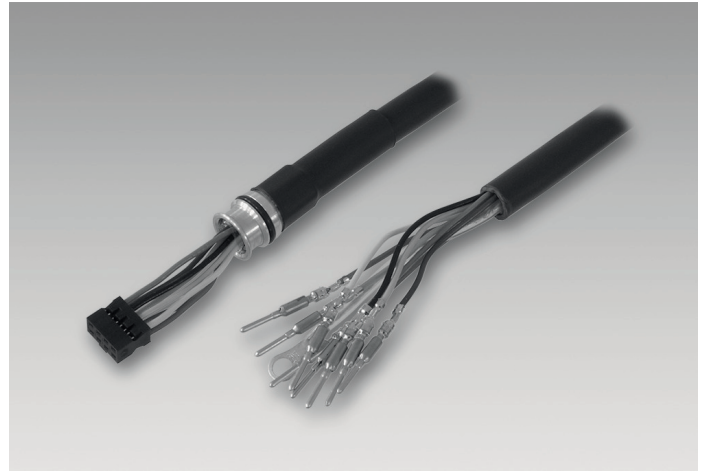


### Technical data

#### Cable specifications

Weight approx.	20 g
Cable length	0.2 m

#### Terminal assignment

 
Connector	Core colour
Pin 1	red
Pin 2	blue
Pin 3	green
Pin 4	brown
Pin 5	grey
Pin 6	black
Pin 7	pink
Pin 8	white
shield = sleeve	transparent



#### Cable specifications

Operating temperature	-30...+100 °C (moved cable)
Outer diameter	≈ 7 mm

### Dimensions

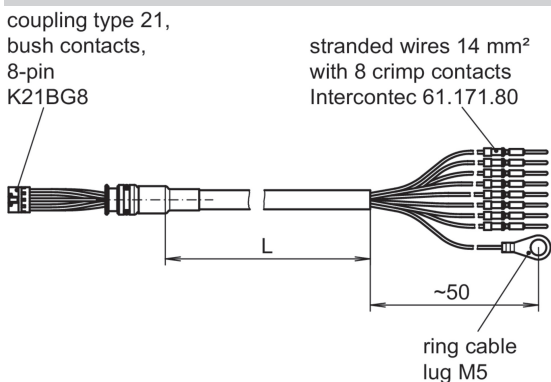

### Suitable for

ITD21H00, ITD22H00, ITD22H00 SIL