

## Connection cable with crimp contacts, 0.2 m

Article number: 11071189

### Overview

- Shielded connection cable with stranded wires 0.14 mm<sup>2</sup> and crimp contacts 61.171.80
- Qualified for operating temperature up to +120 °C
- Assembly by customer possible



 
### Technical data

#### Cable specifications

Weight approx.	20 g
Cable length	0.2 m

#### Terminal assignment


Connector	Core colour
Pin 1	red
Pin 2	blue
Pin 3	green
Pin 4	brown
Pin 5	grey
Pin 6	black
Pin 7	pink
Pin 8	white
shield = sleeve	transparent



#### Cable specifications

Operating temperature	-30...+120 °C
Outer diameter	≈ 6,8 mm

### Dimensions

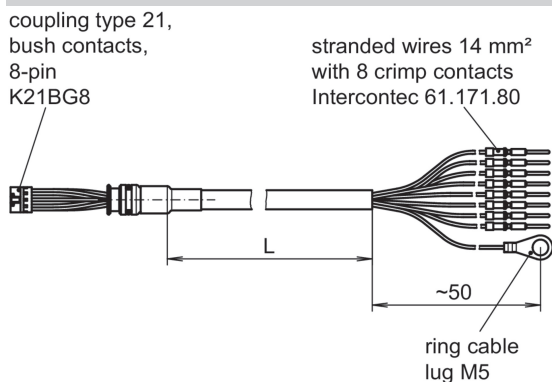

### Suitable for

ITD21H00 HT