

Connector M23 (S2BG12), 2 m cable (RTD)

Article number: 11069601

Overview

- Shielded connection cable with M23-female connector (12-pin) and wire end sleeves for RTD



Technical data

Cable specifications

Material	Cable sheath: PUR black
Weight approx.	200 g
Cable length	2 m


Cable specifications

Operating temperature	-40...+100 °C (fixed cable) -25...+100 °C (moved cable)
Outer diameter	≈ 7.5 mm
Connection	Connector M23, 12-pin

Terminal assignment

Connector S2BG12	Core colour
Pin 1	pink
Pin 2	blue
Pin 3	red
Pin 4	black
Pin 5	brown
Pin 6	green
Pin 7	NC
Pin 8	NC
Pin 9	transparent/shield
Pin 10	NC
Pin 11	NC
Pin 12	NC
NC	grey
NC	white 0.5
NC	white
NC	brown 0.5
NC	yellow
NC	white/brown

Dimensions

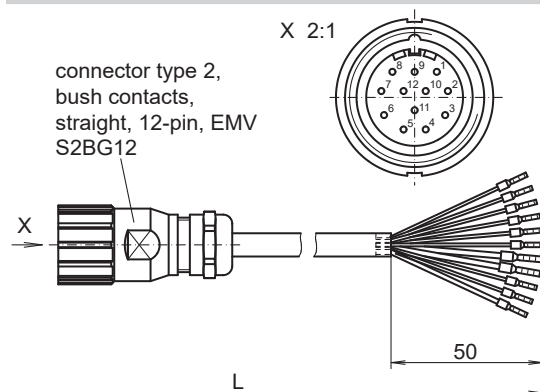

Suitable for

RTD 1 B14 Y 1, RTD 4 A 4 Y 2

