

# Connector M23 (S2BG12), 5 m cable (RTD)

Article number: 11069603

## Overview

- Shielded connection cable with M23-female connector (12-pin) and wire end sleeves for RTD



## Technical data

### Cable specifications

Material	Cable sheath: PUR black
Weight approx.	470 g
Cable length	5 m


### Cable specifications

Operating temperature	-40...+100 °C (fixed cable) -25...+100 °C (moved cable)
Outer diameter	≈ 7,5 mm
Connection	Connector M23, 12-pin


## Terminal assignment

Connector S2BG12 Core colour

Pin 1	pink
Pin 2	blue
Pin 3	red
Pin 4	black
Pin 5	brown
Pin 6	green
Pin 7	NC
Pin 8	NC
Pin 9	transparent/shield
Pin 10	NC
Pin 11	NC
Pin 12	NC
NC	grey
NC	white 0.5
NC	white
NC	brown 0.5
NC	yellow
NC	white/brown

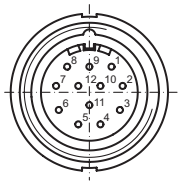

## Dimensions

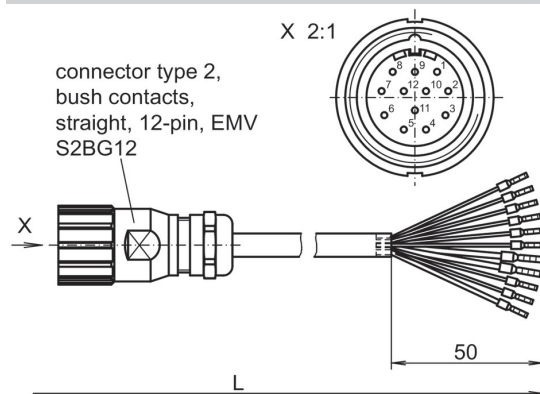

## Suitable for

RTD 1 B14 Y 1, RTD 4 A 4 Y 2