

ESG 32FH0500

Cable 8 wires, 5,0 m

Article number: 11004523

overview

- process interface cable
- M8/8-pin female connector to open wires
- cable carrier compatible
- length 5,0 m
- Phase-Out starting 08/20, alternative via sales



technical data

electrical data

shielding	no
number of poles	8
connectors	M8 female connector, screw lock open wires

mechanical data

use in cable carriers	yes
cable length [m]	5 m

mechanical data

weight	≤ 156 g
material	PUR

interface

data interface	process interface
----------------	-------------------

environmental conditions


operation temperature (static)	-40 ... +90 °C
-----------------------------------	----------------

ESG 32FH0500

Cable 8 wires, 5,0 m

Article number: 11004523

pin assignment

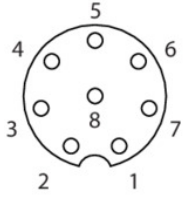

M8	wire color	M8	wire color
1:	WH	5:	GY
2:	BN	6:	PK
3:	GN	7:	BU
4:	YE	8:	RD