


ESG 32SH0500G

Shielded cable 3 wires, 5,0 m

Article number: 10125607

overview

- shielded power cable
- M8/3-pin female connector to open wires
- cable carrier compatible
- length 5,0 m

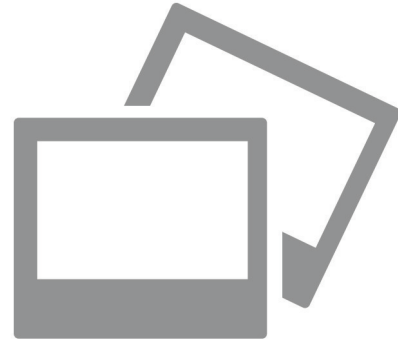

technical data

electrical data

shielding	yes
number of poles	3
connectors	M8 female connector, screw lock open wires

mechanical data

bending radius static	22 mm
bending radius moved in- stallation	44 mm
bending cycles	10000000
use in cable carriers	yes
cable length [m]	5 m

mechanical data

weight	≤ 140 g
material	PUR, halogen-free

interface

data interface	process interface
----------------	-------------------

environmental conditions


flame resistance	DIN EN 60332-2-2 (20s)
halogen-free	DIN VDE 0472 part 815
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-25 ... +80 °C
protection class	IP 65/67 (camera side)

ESG 32SH0500G

Shielded cable 3 wires, 5,0 m

Article number: 10125607

pin assignment

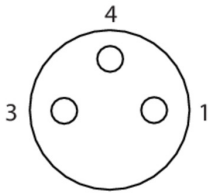

M8	color
----	-------

1:	BN
----	----

4:	BK
----	----

3:	BU
----	----
