


ESG 34AY1000

Connector M12, 4 pin, straight, 10 m, V4A-PP
Article number: 11166446

Overview

- For food & beverage industry applications
- 4 pin unshielded female versions
- Cable coating PP
- Cap nut material in stainless steel V4A
- Ecolab certified
- Follows EHEDG design requirements

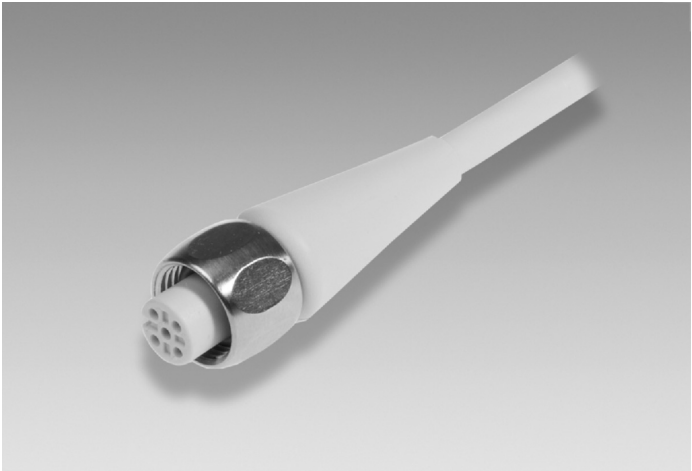

Picture similar

Technical data

General data

Type (head 1)	Straight
Dimension (head 1)	M12
Length	10 m
Material cable jacket	PP
Number of positions	4 pins
Shielding	Unshielded
Protection class	IP 65/67/68/69K


General data

Usage	Connecting cable for Connector type M12
-------	--


General data

Connection type (head 1)	Connector female
Dimension (head 1)	M12
Type (head 1)	Straight
Connection type (head 2)	Free cable end
Particular characteristics	Food & Beverage
Shielding	Unshielded
Material cable jacket	PP
Length	10 m
Number of positions	4 pins
Protection class	IP 65/67/68/69K

Dimension drawing

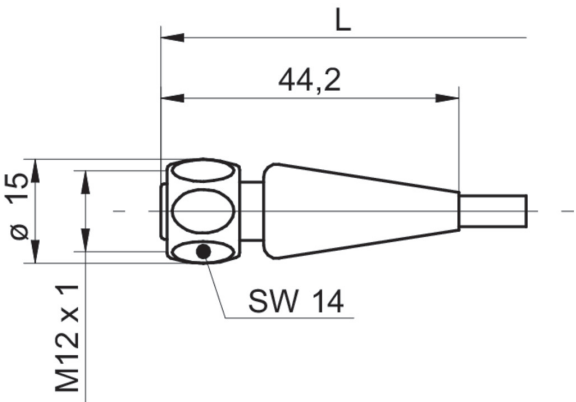

Pin assignment

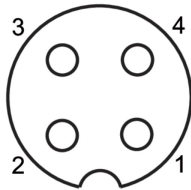

- 1 = BN
- 2 = WH
- 3 = BU
- 4 = BK