

 
ESW 31AH0200G

90° Shielded Cable, 4 wires, 2,0 m

Article number: 11010528

overview

- shielded process interface cable (trigger and flash)
- 90° angled M8/4-pin female connector to open wires
- length 2,0 m
- Phase-Out starting 08/20, alternative via sales



technical data

electrical data

shielding	yes
number of poles	4
connectors	M8 female connector, screw lock open wires

mechanical data

smallest bending radius static	24
smallest bending radius moved installation	48 mm
bending cycles	10000000
use in cable carriers	yes
cable length [m]	2 m

mechanical data

weight	≤ 66 g
material	PUR

interface

data interface	process interface
----------------	-------------------

environmental conditions


flame resistance	DIN EN 60332-2-2 (20s)
halogen-free	DIN VDE 0472 part 815
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-25 ... +80 °C
protection class	IP 67 (camera side)

ESW 31AH0200G

90° Shielded Cable, 4 wires, 2,0 m

Article number: 11010528

pin assignment

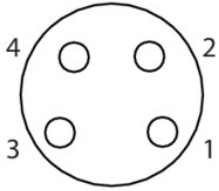

M8	color
1:	BN
2:	WH
4:	BK
3:	BU