


## ESW 33AY2500

Connector M12, 4 pin, angular, 25 m, V4A-PP

Article number: 11166451

### Overview

- For food & beverage industry applications
- 4 pin unshielded female versions
- Cable coating PP
- Cap nut material in stainless steel V4A
- Ecolab certified
- Follows EHEDG design requirements

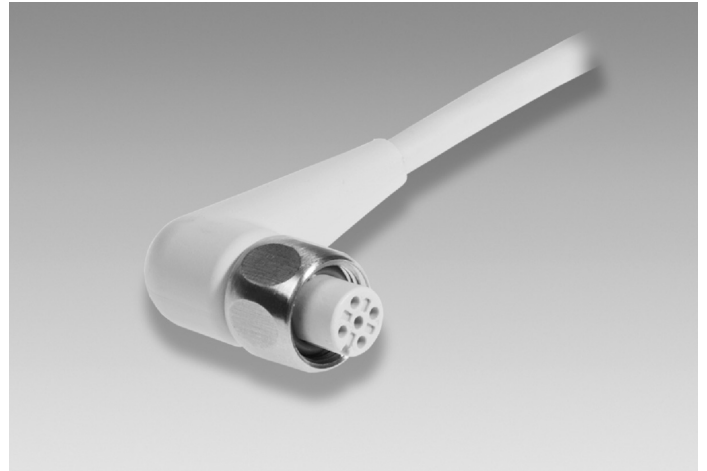

Picture similar

### Technical data

#### General data

Type (head 1)	Angled
Dimension (head 1)	M12
Length	25 m
Material cable jacket	PP
Number of positions	4 pins
Shielding	Unshielded
Protection class	IP 65/67/68/69K


#### General data

Usage	Connecting cable for Connector type M12
-------	--------------------------------------------


#### General data

Connection type (head 1)	Connector female
Dimension (head 1)	M12
Type (head 1)	Angled
Connection type (head 2)	Free cable end
Particular characteristics	Food & Beverage
Shielding	Unshielded
Material cable jacket	PP
Length	25 m
Number of positions	4 pins
Protection class	IP 65/67/68/69K

### Dimension drawing

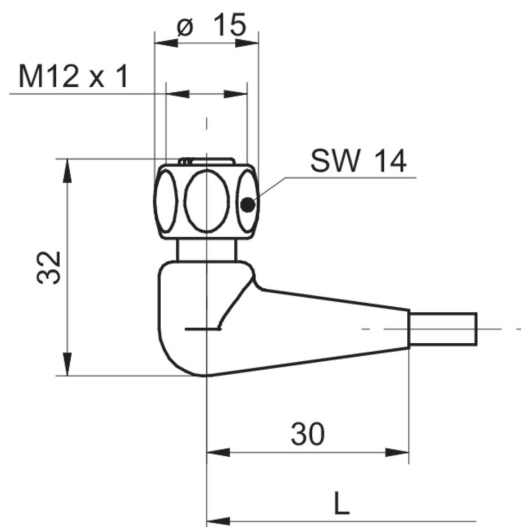

### Pin assignment

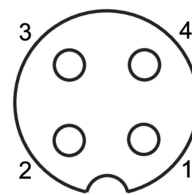

1	=	BN
2	=	WH
3	=	BU
4	=	BK