


Overview

- Diffuse sensors (Leakage sensor)
- -30 ... 70 °C

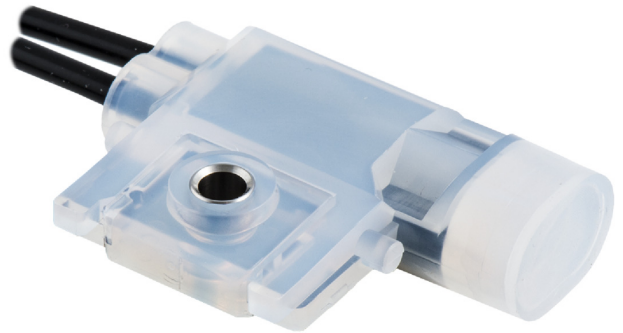

Picture similar



Technical data

General data

Type	Diffuse sensors (Leakage sensor)
Response time / release time	0.05 ... 5 ms
Measurement type	Contact with medium
Type of head (fiber optic cable)	Flat
Width / diameter (head)	13 mm
Height / length (head)	30.9 mm

General data

Depth (head)	9.9 mm
Material (head)	PFA
Bending radius	20 mm
Cable jacket diameter	2.2 mm
Material cable jacket	PFA (chemically resistant)
Material (fiber optic cable)	Plastic
Length (fiber optic cable)	5000 mm
Operating temperature	-30 ... +70 °C

Remarks

- Suitable for constrained conditions.

Dimension drawing

