


## KSG 34A/KSG45AP0500G

Ethernet cable, 5,0 m

Article number: 10165276

### overview

- shielded Ethernet cable
- straight M12/4-pin male connector to RJ45
- length 5,0 m
- Phase-Out starting 08/20, alternative via sales

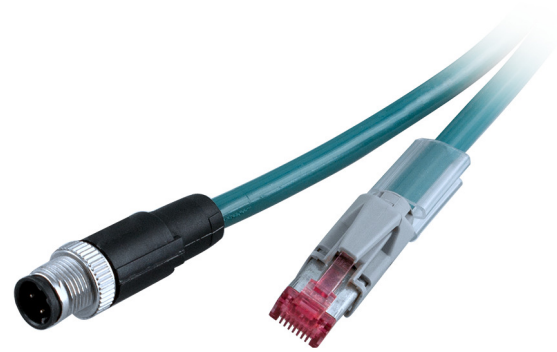

### technical data

#### electrical data

number of poles	4
connectors	M12 male connector, screw lock

#### mechanical data

smallest bending radius static	26 mm
smallest bending radius moved installation	52 mm
use in cable carriers	no
cable length [m]	5 m
weight	≤ 288 g

#### mechanical data

material	PUR
----------	-----

#### interface

data interface	Ethernet
----------------	----------

#### environmental conditions


flame resistance	IEC 60332-1-2
halogen-free	IEC 60754-1
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-20 ... +80 °C
protection class	IP 65/67 (camera side)

# KSG 34A/KSG45AP0500G

Ethernet cable, 5,0 m

Article number: 10165276

## pin assignment

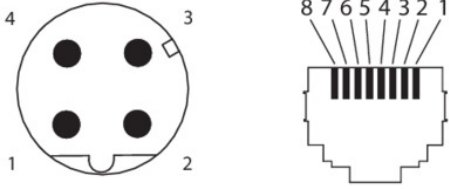

M12	RJ45
1:	1
3:	2
2:	3
4:	6