

KSW 33A/KSG45AP0500G/E

90° angled Ethernet cable, 5,0 m

Article number: 11048594

overview

- shielded Ethernet cable
- 90° angled M12/4-pin male connector to RJ45
- length 5,0 m



technical data

electrical data

number of poles	4
connectors	M12 male connector, angled, screw lock RJ45

mechanical data

bending radius static	26 mm
bending radius moved in-stallation	52 mm
use in cable carriers	no
cable length [m]	5 m
weight	≤ 295 g

mechanical data

material	PUR
----------	-----

interface

data interface	Ethernet
----------------	----------

environmental conditions


flame resistance	DIN EN 60332-1-2
halogen-free	IEC 60754-1
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-20 ... +80 °C
protection class	IP 65/67 (camera side)

KSW 33A/KSG45AP0500G/E

90° angled Ethernet cable, 5,0 m

Article number: 11048594

pin assignment

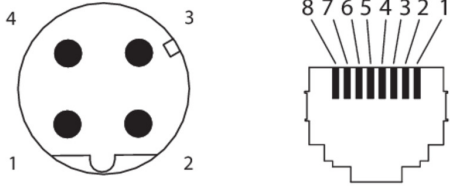

M12	RJ45
1:	1
3:	2
2:	3
4:	6